

Information on Components Used

Connector / Hood

CENT / GLCT / GRPCH



Connector	
Manufacturer	Misumi
Model Number	RC-*0**0
More Information	OP.70

ND76



Connector	
Manufacturer	DDK
Model Number	57-30**0-D76
Rated Current	5A or less
Rated Voltage	500 VAC or less
More Information	OP.73


DCEN / DPCEN / DHCEN / ZHCEN GRNC / GRNCH / GRPCD



Angle Connector (DCEN Only)	
Manufacturer	DDK
Model Number	57JE-B**H-L12*-3F
Rated Current	5A or less
Rated Voltage	500 VAC or less
More Information	OP.72

Straight Connector	
Manufacturer	DDK
Model Number	57-*0**0
Rated Current	5A or less
Rated Voltage	500 VAC or less
More Information	OP.70

NPLCE / GRNCF

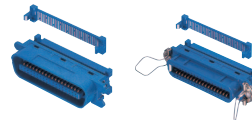

Connector	
Manufacturer	DDK
Model Number	57F-*0**0-20S
Rated Current	1A or less
Rated Voltage	250 VAC or less
More Information	OP.75

ND8 / GRNC8



Connector / Hood	
Manufacturer	DDK
Model Number	57FE-30**0-20N-D8-3F
Rated Current	1A or less
Rated Voltage	250 VAC or less
More Information	OP.76

DDCEN / GRNCD



Connector	
Manufacturer	DDK
Model Number	57-40**0
Rated Current	5A or less
Rated Voltage	500 VAC or less
More Information	OP.71


Crimp Terminal



Y Type Crimp Terminals	
Manufacturer	Daido Solderless Terminal Mfg. Co.
Model Number	F0.3-3 Equivalent
Size	3.2mm
Outer Width	5.2mm
More Information	OP.468



Round Type Crimp Terminals	
Manufacturer	Daido Solderless Terminal Mfg. Co.
Model Number	0.3-3 Equivalent
Size	3.2mm
Outer Width	5.2mm
More Information	OP.464

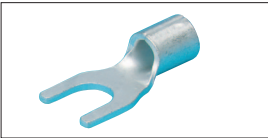

Y Type Crimp Terminals	
Manufacturer	Daido Solderless Terminal Mfg. Co.
Model Number	F0.08-3 Equivalent
Size	3.2mm
Outer Width	5.2mm
More Information	OP.468

The Y type crimp terminals are for M3 screw terminal block. The crimp terminal used is changed according to the thickness of the cable used.

Multi-Core Cable

SB Cable



Manufacturer	Misumi
Model Number	SS30WS
Standard Acquired	AWM20276
Rated Temperature	80°C
Flame Retardance	VW-1SC
Bending Radius mm (Fixed Parts)	Finished Outer Diameter x 8
Bending Radius mm (Movable Parts)	—
More Information	OP.1339

E Cable



Manufacturer	Misumi
Model Number	NA2464
Standard Acquired	AWM2464
Rated Temperature	0 ~ 80°C
Flame Retardance	—
Bending Radius mm (Fixed Parts)	Finished Outer Diameter x 8
Bending Radius mm (Movable Parts)	—
More Information	OP.1293

KS Cable



Manufacturer	Misumi
Model Number	SS300SB
Standard Acquired	AWM2464
Rated Temperature	0 ~ 80°C
Flame Retardance	VW-1
Bending Radius mm (Fixed Parts)	Finished Outer Diameter x 6
Bending Radius mm (Movable Parts)	—
More Information	OP.1291

RS Cable



Manufacturer	Misumi
Model Number	SS300RSB
Standard Acquired	AWM2464
Rated Temperature	0 ~ 80°C
Flame Retardance	VW-1
Bending Radius mm (Fixed Parts)	Finished Outer Diameter x 6
Bending Radius mm (Movable Parts)	Finished Outer Diameter x 6
More Information	OP.1505

Dsub
Connector
Included Cable
MIL Socket
Connector
Included Cable
FCN
Connector
Included Cable
Connector Included
Conversion/Branch
Cable

Centronics
Connector
Included Cable
Cable with IEEE
1284 Half Pitch
Connector
MR
Connector
Included Cable
PCR Half Pitch
Connector
Included Cable
PCS Half Pitch
Connector
Included Cable
HDBA / HDR
Connector
Included Cable
DX31 Half Pitch
Connector
Included Cable
8840 Half Pitch
Connector
Included Cable
Cable with Han
Waterproof
Connector