

Delivery  
交货期

## 发货日期

1~10袋 次日(当日)

11袋~ 另定

17:00前订购的库存品可当日发货。


Discount  
折扣

## 折扣表

1~9袋 标准单价

10~19袋 19% off

20袋~ 24% off

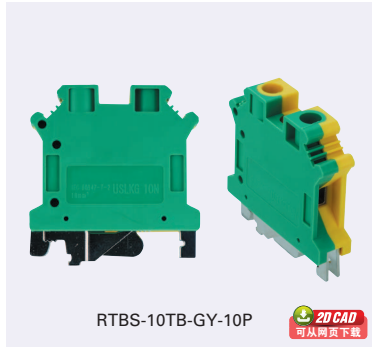

RTBS-10TB-GY-10P

2D CAD  
可从网页下载

## 特长 通用型螺丝固定接地端子

- 侧面接线型, 2通道产品。
- 1袋10个装, 可根据不同需求自由组合。
- 材料: PA66 (UL94-V0)。
- 产品RTBS-2.5TB-\* 和RTBS-5TB-\* 的跨接件在 [1115页](#)。
- 适合安装于U型导轨 ([1598页](#))。

Order  
订货范例

型号

RTBS-10TB-GY-10P

## 规格表

型号	每袋装	颜色	额定电压		额定电流			额定截面积	
			UL/CSA额定	IEC额定	UL额定	CSA额定	IEC额定	UL/CSA额定	软导线
RTBS-2.5TB-GY-10P	10个	黄绿色	AC300V	AC690V	20A	20A	32A	AWG24~14	0.2~2.5mm <sup>2</sup>
RTBS-3TB-GY-10P			AC600V	AC800V					
RTBS-5TB-GY-10P					65A	65A	76A	AWG24~6	0.5~6.0mm <sup>2</sup>
RTBS-10TB-GY-10P									

1袋起接受订购!

## 附件表

接地端子	接线端子 <a href="#">1112页</a>	盖板/隔板 <a href="#">1114页</a>	固定件 <a href="#">1114页</a>	记号板 <a href="#">1115页</a>	DIN导轨
RTBS-2.5TB-GY-10P	RTBS-2.5TB-G-10P	RTBS-2.5EI-G-10P	MAES-35S-10P	RTBS-5MC-10P	<a href="#">1598页</a>
RTBS-3TB-GY-10P	RTBS-3TB-G-10P	RTBS-3EI-G-10P		RTBS-3MC-10P	
RTBS-5TB-GY-10P	RTBS-5TB-G-10P			RTBS-5MC-10P	
RTBS-10TB-GY-10P	RTBS-10TB-G-10P			RTBS-10MC-10P	
RTBS-2.5TB-GY-10P	RTBS-2.5TB-BE-10P	RTBS-2.5EI-OR-10P		RTBS-5MC-10P	
RTBS-3TB-GY-10P	RTBS-3TB-BE-10P	RTBS-3EI-OR-10P		RTBS-3MC-10P	
RTBS-5TB-GY-10P	RTBS-5TB-BE-10P			RTBS-5MC-10P	
RTBS-10TB-GY-10P	RTBS-10TB-BE-10P			RTBS-10MC-10P	

## 尺寸图

(单位: mm)

