

When ordering, select Part Number and Values from Selection Steps ①~③.


Ordering Example
 Part Number (①Type-②M) - ③L
C-CLDMM6 - 16
C-CLDFF8 - 10

Clamp Levers




CAD 2D 3D
 *3D CAD data become available over the Web as required. All of them will get ready at the end of July.

Type	Thread	Lever		Thread		Spring	
		Material	Surface Treatment	Material	Surface Treatment	Material	Surface Treatment
C-CLDMM	Male Thread	Zinc Alloy	Electrophoresis	SUM22L	Black Oxide	Spring Steel	Zinc Plating
C-CLDFF	Female Thread						

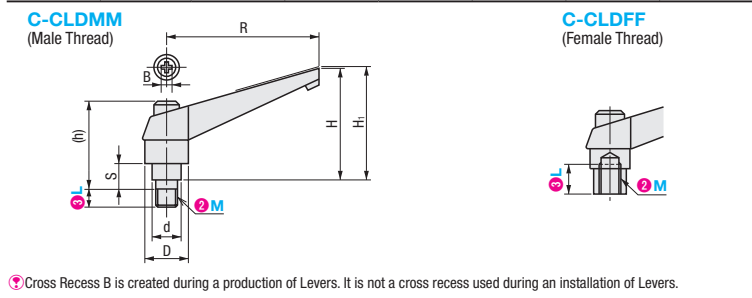

Part Number ①TYPE	②M	③L	Lever Color	R	H	H ₁	(h)	S	D	d	Number of Serrated Teeth	B	Max. Load F _{max} (N)	Max. Tightening Force P _{max} (kN)	Reference Mass (g)
	8	25 30	68	40	40	31	10	18	12	12	5	95	3.8	60	
	10	20 40	83	52	52	38	10	18	12	12	5	152	5.9	160	
	12	25 50	97	57	57	42	12	25	17	17	6	223	8.6	181	
C-CLDFF Female Thread	6	8	52	33	33	25	6	14	9	9	4	55	2.1	26	
	8	10	68	40	40	31	10	18	12	12	5	95	3.8	49	
	10	10	83	52	52	38	10	18	12	12	5	152	5.9	79	
	12	15	97	57	57	42	12	25	17	17	6	223	8.6	134	

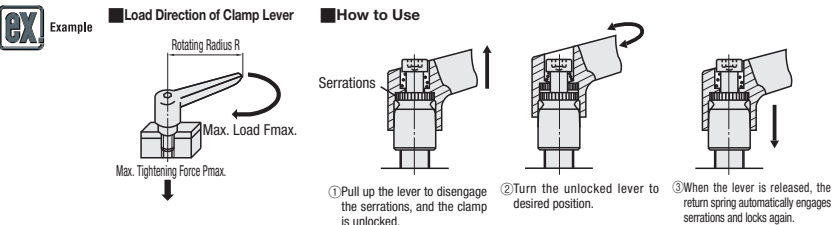

When ordering, select Part Number and Values from Selection Steps ①~③.


Ordering Example
 Part Number (①Type-②M) - ③L
C-LRGN8 - 83

Stationary Levers



CAD 2D 3D
 *3D CAD data become available over the Web as required. All of them will get ready at the end of July.

Type	Lever		Handle
	Material	Surface Treatment	Material
C-LRGN	Carbon Steel for Mechanical Structure	Chrome Plating	ABS

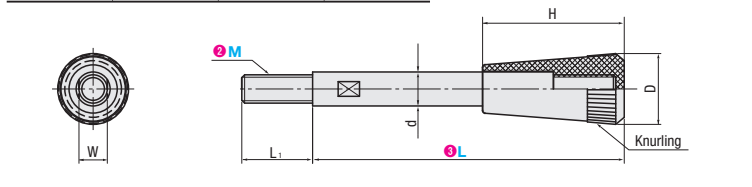

Part Number ①TYPE	②M	③L	Handle Color	L ₁	d	D	H	W	Reference Mass (g)
	10	125 150	14	12	25	50	10	135	
	12	132 156	16	16	32	60	13	245	


Ordering Example
 Part Number (Type-M)
C-GRMS8

Revolving Handles



CAD 2D 3D

Type	Handle		Screw	
	Material	Surface Treatment	Material	Surface Treatment
C-GRMS	Carbon Steel for Mechanical Structure	Chrome Plating	Carbon Steel for Mechanical Structure	Chrome Plating
C-GRMSS	Carbon Steel for Mechanical Structure	Chrome Plating	Carbon Steel for Mechanical Structure	Black Oxide

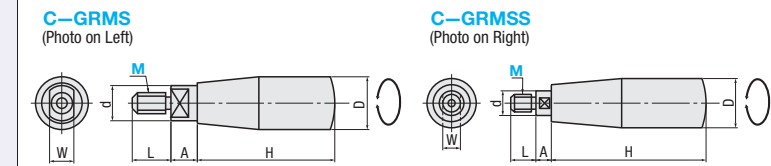

Part Number Type	M	D	d	H	L	W	A	Reference Mass (g)
	10	22	15	80	16	13	10	210
	12	25	18	100	18	16	12	355
C-GRMSS	6	16	6	50	12	5	12	65
	8	18	8	63	14	6	12	115
	10	22	10	80	16	8	12	195

When ordering, select Part Number and Values from Selection Steps ①~③.


Ordering Example
 Part Number (①Type-②M) - ③H
C-GRW8 - 63

Revolving Handles with Hex Socket



CAD 2D 3D

Type	Handle	Thread	
	Material	Material	Surface Treatment
C-GRW	Phenol	Carbon Steel for Mechanical Structure	Trivalent Chromate

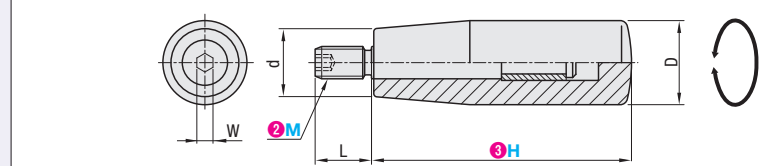

Part Number ①Type	②M (Coarse)	③H	D	d	W	L	Mass (g)
	10	80	26	20	4	18	96
	12	100	28	22	5	22	135

