


Tapered Revolving Handles / Revolving Handles with Hex Socket / Fold-Down Revolving Handles

Flat Revolving Handles / Miniature Revolving Handles / Miniature Revolving Handles - Stainless Steel / Revolving Ball Knobs


Tapered Revolving Handles

Type	①Handle	②Screw	③Nut
	M Material	M Material S Surface Treatment	M Material S Surface Treatment
GRC	Nylon6 (Black)	SWRM Trivalent Chromate	SUM24L Chrome Plating

Ⓜ Only the plastic grip rotates after attached to a handwheel.

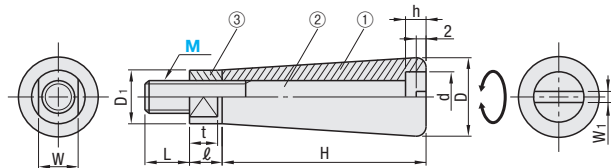

How to Mount

 


RoHS 10


Part Number		D	D1	d	H	h	l	t	W	W1	L	Mass (g)	Unit Price
Type	M (Coarse)												
GRC	8	20	13	12	55	5.5	8	6.5	10	2	11	40	
	10	25	16	15	68		10	8	14		18	100	
	12	30	21	20	85	10	13	9.5	17	2.5	23	180	

Revolving Handles With Hex Socket

Type	Handle	Screw
	M Material	M Material S Surface Treatment
GRW	Phenol SUM21	Trivalent Chromate

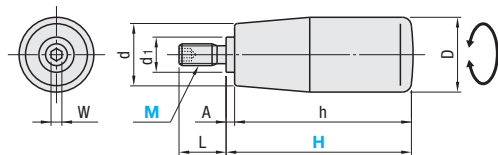

How to Mount

 


RoHS 10

Part Number		D	d	d1	h	W	L	A	Mass (g)	Unit Price
Type	M (Coarse) - H									
GRW	6-28.5	14	11	8	28		10	0.5	13	
	6-42.5	18	15	10	40	3	12	2.5	29	
	6-52.5	21	17		50		13	2.5	42	
	8-40	20	17	10	39	4	12		24	
	8-55				54				44	
	10-67	23	20	12	66	5			74	
	10-75	23	20	12	74	5	16		77	

Fold-Down Revolving Handles

Type	Handle	Screw	Lock Nut
	M Material	M Material S Surface Treatment	M Material S Surface Treatment
GRMBM	Nylon S45C	Chrome Plating	S45C Chrome Plating

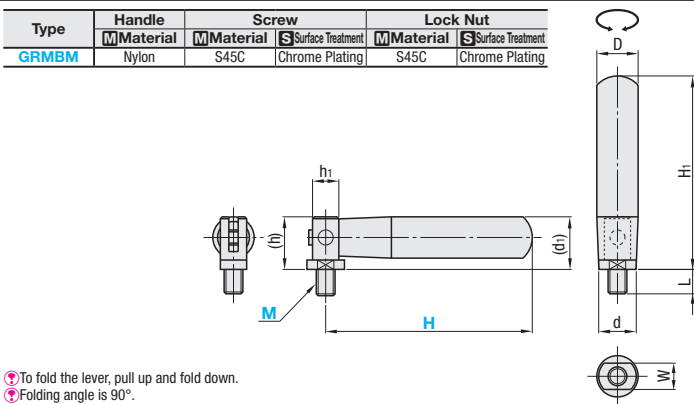

Ⓜ To fold the lever, pull up and fold down.
Ⓜ Folding angle is 90°.

RoHS 10

Part Number		H	D	d	(h)	L	h1	H1	(d1)	W	Mass (g)	Unit Price
Type	M (Coarse)											
GRMBM	8	55	20	16	21	12.5	9	55	24	12	42	
	10	81	20	16	28	12.5	9	81	30	14	80	
	10	104	23	19	28	16	11	104	31	14	155	


Ordering Example: Part Number - H

GRC8	- 40
GRW8	- 55
GRMBM8	- 55

Flat Revolving Handles

Type	Handle	Screw	Included Screw
	M Material	M Material S Surface Treatment	M Material S Surface Treatment
GRMLM	Phenol Resin	SS400 Trivalent Chromate	Structural Alloy Steel Trivalent Chromate

Ⓜ To fold the lever, pull up and fold down.
* There is a locating hole of Ø2.5 and 2.5mm in depth.

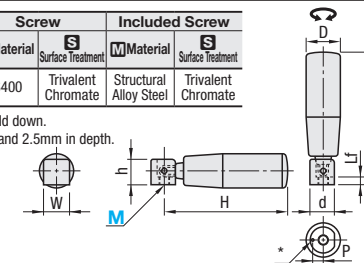


Part Number		H	D	d	h	Lf	H1	W	P	Included Screw	Mass (g)	Unit Price
Type	M (Coarse)											
GRMLM	5	53	18	15.5	15	5	57	17	5.25	M5x10	55	
	6	80	23	18.5	19.5	6	87	20	6.5	M6x10	115	
	8	95	26	18.5	19.5	6	102	20	7	M8x14	137	

Ordering Example: Part Number GRMLM6

Miniature Revolving Handles

Type	Shape	Handle	Screw
		M Material	M Material S Surface Treatment
GRH	Threaded	Nylon 6	SUM22L Black Oxide
GRF	Tapped		


Ⓜ Only the plastic grip rotates after attached to a handwheel.

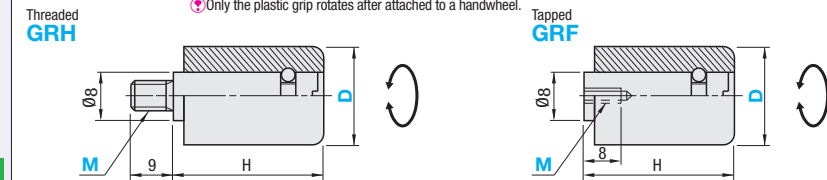

Part Number		Handle Color	H	Mass (g)	Unit Price	Part Number		Handle Color	H	Mass (g)	Unit Price
Type	M (Coarse) - D					Type	M (Coarse) - D				
Threaded GRH	6-13	B (Black)	18.8	13		Tapped GRF	5-13		18.8	8	
	6-14	W (White)	20.8	14			5-14	B (Black)	20.8	9	
	6-16		23.8	16			5-16		23.8	10	

Miniature Revolving Handles - Stainless Steel

Type	M Material	S Surface Treatment
GRMSM	SUS304	Electrolytic Polishing

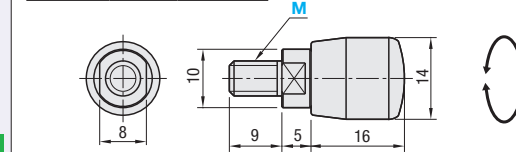


RoHS 10


Part Number		Mass (g)	Unit Price
Type	M (Coarse)		
GRMSM	6	21	

Revolving Ball Knobs

Type	Ball	Screw
	M Material	M Material S Surface Treatment
PBG	Phenol Resin Brass (insert)	SUM23 Electroless Nickel Plating

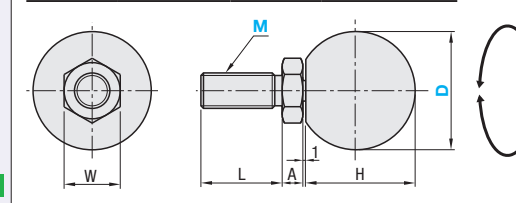

RoHS 10

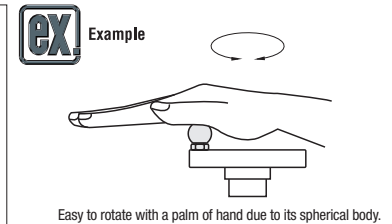

Part Number		D	H	L	W	A	Mass (g)	Unit Price
Type	M (Coarse)							
PBG	6	20	18	7	10	3.6	12	
		25	23				17	
		30	28				25	
	8	20	18	8	13	5	19	
		25	23				25	
		30	28				33	
	10	20	18	10	17	6	49	
		25	23					
		30	28					

Ordering Example: Part Number - D - Handle Color

GRMLM5	- 13	- W
GRH6	- 16	- B
GRF5	- 25	
GRMSM6		
PBG8		