

Note that, for some of the types shown here, order might be unable to be received by the MISUMI Thailand, Malaysia, Indonesia, and/or India offices.

# Phillips Truss Machine Screws


Stainless Steel (Available in Box)

# Phillips Truss Machine Screws

Stainless Steel (Available in Single item)



Type	Material
BOX-TRSS	SUS304 Equivalent

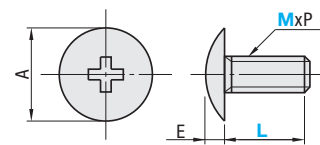

MxP (Coarse)	A	E	Phillips No.
2 x0.4	4.5	1.2	1
2.5x0.45	5.7	1.5	1
2.6x0.45	5.9	1.6	1
3 x0.5	6.9	1.9	1
4 x0.7	9.4	2.5	2
5 x0.8	11.8	3.1	2
6 x1.0	14	3.7	3

Can be ordered as a separate item. P234

Please specify in box quantity when ordering. One box is shipped for an order of 1.


Ordering Example  
Part Number  
BOX-TRSS5-10

Box package is cost-saving for in-house stock or when large quantities are needed.

Part Number		Unit Price 1 to 10 boxes		Pcs./ Box	
Type	M-L	Price per pkg.	1 Box		
BOX-TRSS (Stainless Steel)	2- 3			2,000 pcs./box	
	4				
	5				
	6				
	8				
	2.5- 3				
	4				
	5				
	6				
	8				
	10				
	2.6- 3				
	4				
	5				
	6				
	8				
	10				
	3- 5				1,000 pcs./box
	6				
	8				
10					
4- 5			500 pcs./box		
6					
8					
10					
5- 8			500 pcs./box		
10					
12					
15					
20					
6-10			300 pcs./box		
12					
15					
20					



Type	Material	Surface Treatment
BTRSS	SWCH Equivalent	Trivalent Chromate
TRSS	SUS304 Equivalent	-

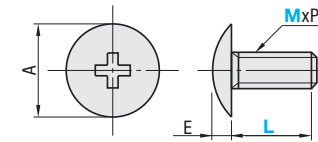

MxP (Coarse)	A	E	Phillips No.
2x0.4	4.5	1.2	1
2.5x0.45	5.7	1.5	1
2.6x0.45	5.9	1.6	1
3x0.5	6.9	1.9	1
4x0.7	9.4	2.5	2
5x0.8	11.8	3.1	2
6x1.0	14	3.7	3

BTRSS (Trivalent Chromate)

Part Number		Unit Price	Volume Discount Rate			
Type	M - L	1 ~ 29 pc(s)	30 ~ 99 pcs	100 ~ 249 pcs	250 ~ 500 pcs	
BTRSS	3 - 4					
	5					
	6					
	8					
	10					
	12					
	4 - 4					
	5					
	6					
	8					
	10					
	12					
	15					
	5 - 5					
	6					
8						
10						
12						
15						
20						
6 - 8						
10						
12						
15						
20						

Ordering Example  
Part Number  
BTRSS5-10

TRSS (Stainless Steel)

Part Number		Unit Price	Volume Discount Rate			
Type	M - L	1 ~ 29 pc(s)	30 ~ 99 pcs	100 ~ 149 pcs	150 ~ 500 pcs	
TRSS	2 - 3					
	4					
	5					
	6					
	8					
	2.5 - 3					
	4					
	5					
	6					
	8					
	10					
	2.6 - 3					
	4					
	5					
	6					
8						
10						
3 - 4						
5						
6						
8						
10						
12						
4 - 4						
5						
6						
8						
10						
12						
15						
5 - 6						
8						
10						
12						
15						
20						
6 - 8						
10						
12						
15						
20						