


Nuts JIS Class 1 / JIS Class 3

Available in Box



Nuts - JIS Class 1

Type	Material	Surface Treatment
BOX-LBNR	SAE1008 (SWRCH Equivalent)	Trivalent Chromate
BOX-SLBNR	SUS304	-

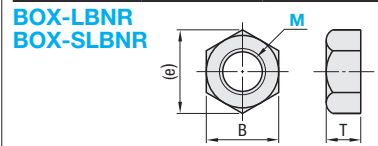

MxP (Coarse)	B	(e)	T
2 x0.4	4	4.6	1.6
2.5x0.45	5	5.8	2
2.6x0.45	5	5.8	2
3 x0.5	5.5	6.4	2.4
4 x0.7	7	8.1	3.2
5 x0.8	8	9.2	4
6 x1.0	10	11.5	5
8 x1.25	13	15	6.5
10 x1.5	17	19.6	8


Can be ordered as a separate item. P.240



RoHS10

Nuts - JIS Class 3

Type	Material	Surface Treatment
BOX-KNTR	SAE1008 (SWRCH Equivalent)	Trivalent Chromate
BOX-SKNTR	SUS304	-

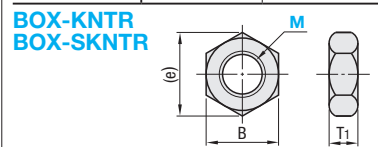

MxP (Coarse)	B	(e)	T ₁
3x0.5	5.5	6.4	1.8
4x0.7	7	8.1	2.4
5x0.8	8	9.2	3.2
6x1.0	10	11.5	3.6
8x1.25	13	15	5
10x1.5	17	19.6	6

Can be ordered as a separate item. P.240

Please specify in box quantity when ordering. One box is shipped for an order of 1.

Ordering Example
Part Number
BOX-LBNR2.5
BOX-SKNTR10

Box package is cost-saving for in-house stock or when large quantities are needed.

Part Number	Unit Price 1 to 10 boxes		Pcs./Box
	Type	M	
BOX-LBNR	2		1,000 pcs./box
	2.5		
	2.6		
	3		
	4		
	5		
	6		
	8		
	10		
			200 pcs./box

For orders larger than indicated quantity, please check with WOS.

Part Number	Unit Price 1 to 10 boxes		Pcs./Box
	Type	M	
BOX-SLBNR (Stainless Steel)	2		1,000 pcs./box
	2.5		
	2.6		
	3		
	4		
	5		
	6		
	8		
	10		
			200 pcs./box

For orders larger than indicated quantity, please check with WOS.

Part Number	Unit Price 1 to 10 boxes		Pcs./Box
	Type	M	
BOX-KNTR	3		1,000 pcs./box
	4		
	5		
	6		
	8		
	10		
			200 pcs./box

For orders larger than indicated quantity, please check with WOS.

Part Number	Unit Price 1 to 10 boxes		Pcs./Box
	Type	M	
BOX-SKNTR (Stainless Steel)	3		1,000 pcs./box
	4		
	5		
	6		
	8		
			500 pcs./box
			200 pcs./box

For orders larger than indicated quantity, please check with WOS.

Nuts

Single Item Sale

Nuts (LBNR, SLBNR, KNTR, SKNTR) can be ordered by cost saving boxes. P.239

Nuts

(JIS Class 1) LBNR (Right-Hand Thread) SLBNR (SUS Right-Hand Thread) LBNL (Left-Hand Thread) SLBL (SUS Left-Hand Thread)	(JIS Class 3) KNTR (Right-Hand Thread) SKNTR (SUS Right-Hand Thread) KNTL (Left-Hand Thread)	ANN (Right-Hand Fine Thread) SANN (SUS Right-Hand Fine Thread) TNTR (Thin Right-Hand Fine Thread) STNTR (SUS Thin Right-Hand Fine Thread)
--	---	--

M	(Coarse) Pitch	B	(e)	T	T ₁
2	0.4	4	4.6	1.6	1.2
2.5	0.45	5	5.8	2	1.6
2.6	0.45	5	5.8	2	1.6
3	0.5	5.5	6.4	2.4	1.8
4	0.7	7	8.1	3.2	2.4
5	0.8	8	9.2	4	3.2
6	1.0	10	11.5	5	3.6
8	1.25	13	15	6.5	5
10	1.5	17	19.6	8	6
12	1.75	19	21.9	10	7
16	2.0	24	27.7	13	10
20	2.5	30	34.6	16	12
24	3.0	36	41.6	19	14

ANN: Material: (Steel) Steel, Surface Treatment: Trivalent Chromate Plating
LBNR, LBNL, KNTR, KNTL, TNTR: Material: SWCH Equivalent, Surface Treatment: Trivalent Chromate Plating
SLBNR, SLBL, SANN, SKNTR, STNTR: Material: SUS304 Equivalent

Part Number	LBNR		KNTR		SLBNR		SKNTR		LBNL		KNTL		SLBNL	
	Unit Price	Volume Discount Rate	Unit Price	Volume Discount Rate	Unit Price	Volume Discount Rate	Unit Price	Volume Discount Rate	Unit Price	Volume Discount Rate	Unit Price	Volume Discount Rate	Unit Price	Volume Discount Rate
Type	M	1 - 9 pc(s), 10 - 49 pcs, 50 - 200 pcs.	1 - 9 pc(s), 10 - 49 pcs, 50 - 200 pcs.	1 - 9 pc(s), 10 - 49 pcs, 50 - 200 pcs.	1 - 9 pc(s), 10 - 49 pcs, 50 - 200 pcs.	1 - 9 pc(s), 10 - 49 pcs, 50 - 200 pcs.	1 - 9 pc(s), 10 - 49 pcs, 50 - 200 pcs.	1 - 9 pc(s), 10 - 49 pcs, 50 - 200 pcs.	1 - 9 pc(s), 10 - 49 pcs, 50 - 200 pcs.	1 - 9 pc(s), 10 - 49 pcs, 50 - 200 pcs.	1 - 9 pc(s), 10 - 49 pcs, 50 - 200 pcs.	1 - 9 pc(s), 10 - 49 pcs, 50 - 200 pcs.	1 - 9 pc(s), 10 - 49 pcs, 50 - 200 pcs.	1 - 9 pc(s), 10 - 49 pcs, 50 - 200 pcs.
LBNR	2													
LBNL	2.5													
SLBNR	2.6													
SLBNL	3													
KNTR	4													
KNTL	5													
SKNTR	6													
	8													
	10													
	12													
	16													
	20													
	24													

No specifications available for sizes with no prices shown.

Part Number	B	(e)	T	ANN		SANN		Part Number	B	(e)	TNTR		STNTR	
				Unit Price	Volume Discount Rate	Unit Price	Volume Discount Rate				Unit Price	Volume Discount Rate	Unit Price	Volume Discount Rate
Type	M (Fine)			1 - 99 pc(s), 100 - 200 pcs.	1 - 99 pc(s), 100 - 200 pcs.	1 - 99 pc(s), 100 - 200 pcs.	1 - 99 pc(s), 100 - 200 pcs.	Type	M-P-T ₂		1 - 99 pc(s), 100 - 200 pcs.	1 - 99 pc(s), 100 - 200 pcs.	1 - 99 pc(s), 100 - 200 pcs.	1 - 99 pc(s), 100 - 200 pcs.
ANN SANN	4-0.5	7	8.1					TNTR STNTR	6-0.75-1.5	8	9.2			
	5-0.5	8	9.2	4					6-0.75-2	9	10.4			
	6-0.75	10	11.5	5					8-0.75-2	10	11.5			
	8-0.75	13	15	6					10-0.75-2	14	16.2			
	8-1.0			6					10-1.0-2	14	16.2			
	10-1.0			6					10-1.0-3	14	16.2			
	10-1.25	17	19.6	8					10-1.0-4	14	16.2			
	12-1.0			6					12-1.0-2	14	16.2			
	12-1.25			6					12-1.0-3	17	19.6			
	12-1.5	19	21.9	10					12-1.0-4	17	19.6			
	14-1.5			11					16-1.0-2.5	19	21.9			
	16-1.5	22	25.0	8										
	20-1.5	24	27.7	10										
	30	34.6	10											

Ordering Example
Part Number
SLBNR10
ANN10-1.25
TNTR10-1.0-4