


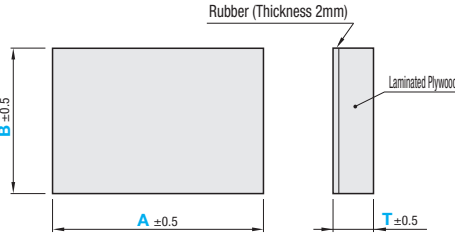
Single-Sided Rubber Glued Laminated Plywood

Standard / Antistatic




NTBD (Standard Type)
 NTBH (Standard Type)
 ATBD (Antistatic Type)
 ATBH (Antistatic Type)


Type	Material	Color
NTBD NTBH	Laminated Plywood (Poplar)	Light Gray
ATBD ATBH	Glued Chloroprene Synthetic Rubber	Light Green




NTBD
ATBD

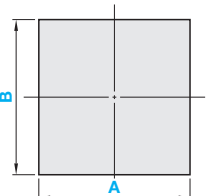


NTBDA
ATBDA

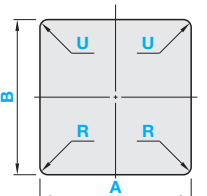


NTBDB
ATBDB

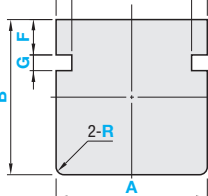


NTBDC
ATBDC

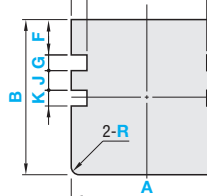


NTBH
ATBH

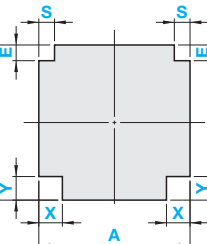


NTBHA
ATBHA

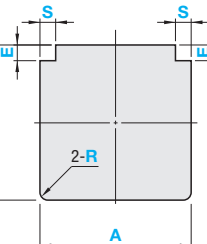


NTBHB
ATBHB

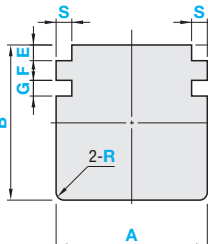

NTBHC
ATBHC

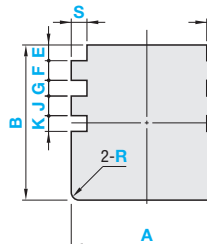

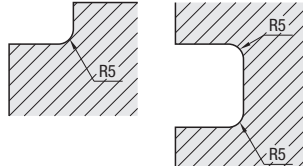

⚠ The shapes of notched angle are as shown on the left-side figure.

Part Number		A 1mm Increment	B 1mm Increment	Color	R	U	E	G	K	S	X	Y	F	J	
Type	T Selection				15-60 1mm Increment								1mm Increment		
NTBD	10 14 20	200~1200	200~1000	G (Light Gray)	-	-	-	-	-	-	-	-	-	-	
NTBDA					0	10	-	-	-	-	-	-	-	-	-
NTBDB					20	-	G	-	S	-	-	-	F	-	-
NTBDC					30	-	G	K	S	-	-	-	F	J	-
NTBH	10 14 20	200~1200	200~1000	L (Light Green)	-	-	-	-	-	-	X	Y	-	-	
NTBHA					0	10	E	-	S	-	-	-	-	-	-
NTBHB					20	E	G	-	S	-	-	-	F	-	-
NTBHC					30	E	G	K	S	-	-	-	F	J	-
ATBD	10 14 20	200~1200	200~1000	L (Light Green)	-	-	-	-	-	-	-	-	-	-	
ATBDA					0	10	-	G	-	S	-	-	F	-	-
ATBDB					20	-	G	K	S	-	-	-	F	J	-
ATBDC					30	-	E	-	S	-	-	X	Y	-	-
ATBH	10 14 20	200~1200	200~1000	L (Light Green)	-	-	-	-	-	-	X	Y	-	-	
ATBHA					0	10	E	-	S	-	-	-	-	-	-
ATBHB					20	E	G	-	S	-	-	-	F	-	-
ATBHC					30	E	G	K	S	-	-	-	F	J	-


Ordering Example: Part Number - A - B - Color - R - U - E, G, K, S, X, Y, F, J
 ATBHB14 - 800 - 600 - L - R20 - E30 - G30 - S30 - F60

Part Number	A Selection	Unit Price			
		B			
Type	T	200~400	401~600	601~800	801~1000
<Base Plate> NTBD NTBDA NTBDB NTBDC NTBH NTBHA NTBHB NTBHC (Standard Type)	10	200~ 400			
		401~ 600			
		601~ 800			
		801~1000			
	14	200~ 400			
		401~ 600			
		601~ 800			
		801~1000			
	20	200~ 400			
		401~ 600			
		601~ 800			
		801~1000			
<Base Plate> ATBD ATBDA ATBDB ATBDC ATBH ATBHA ATBHB ATBHC (Antistatic Type)	10	200~ 400			
		401~ 600			
		601~ 800			
		801~1000			
	14	200~ 400			
		401~ 600			
		601~ 800			
		801~1000			
	20	200~ 400			
		401~ 600			
		601~ 800			
		801~1000			

Notching Charge (Ex.) Part Number - A - B - Color - R - G · S · F
 Applicable Codes Unit Price/2 Places (Right and Left)
 (Notching) E G K Y
 (Corner R) U R
 Example: ATBDB10 - 800 - 600 - L - R20 - G30 - S30 - F60

⚠ The unit price is for 2 notches provided symmetrically on right and left sides.

Load Capacity Guideline

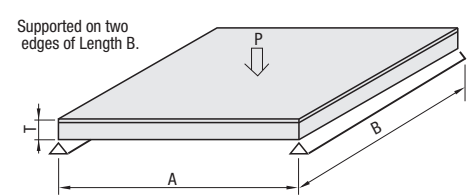

T	Plate Size		Load Reference	
	A	B	(N)	(kgf)
10	900	300	127	13
		600	275	28
	750	333	34	
	1200	300	59	6
600		118	12	
14	900	300	339	35
		600	695	71
		750	861	88
	1200	300	147	15
		600	284	29
		750	366	37
20	900	300	598	61
		600	1216	124
	750	1417	150	
	1200	300	245	25
600		510	52	
		750	647	66

Properties of Rubber

Item	Unit	Rubber Used for NTBD and NTBH	Antistatic Rubber Used for ATBD and ATBH
Specific Gravity	-	1.6	1.2
Elongation	%	450	190
Tensile Strength	MPa	6.7	12.8
Tearing Strength	N/mm	22	30
Specific Volume Resistivity	Ω · cm	2x10 ¹¹	6.9x10 ⁹

⚠ Testing Method: JIS K 6301
 ⚠ The above values are not guaranteed values but an example of measured values.

