

SKD11
6F2G
上下2面サファイア

GROUND PLATES FOR WEDM

ワイヤーカット用プレート(上下2面研磨)

—標準タイプ・板厚(T)0.01mm指定タイプ—




■精度基準

- 基準面直角度 100mmに対し0.015以下
- 板厚平行度 100mmに対し0.008以下
- 平面度 (板厚T) T5.00~10.00 T10.01~20.00 T20.01~35.00 100mmに対し 0.02 0.015 0.01



RoHS

SKD11WP (標準タイプ)
T-SKD11WP (板厚(T)0.01mm指定タイプ)

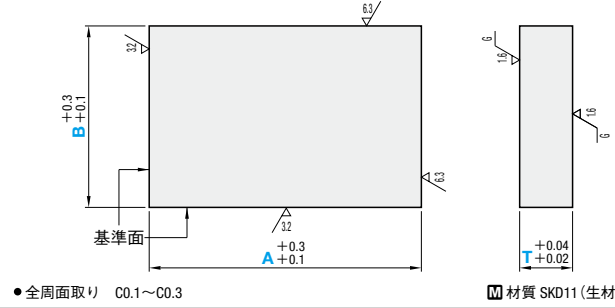

SKD11WP 標準タイプ ¥基準単価

型式	A	B	T	¥基準単価											
				5	6	8	10	13	15	20	25	30	35		
SKD11WP	20	20	20	1,970	1,920	1,900	1,700	1,720	1,750	1,770	1,790	1,810	1,840		
			40	2,040	2,000	1,990	1,760	1,810	1,840	1,910	1,940	2,000	2,040		
			60	2,090	2,050	2,060	1,820	1,870	1,930	2,010	2,060	2,140	2,210		
			80	2,130	2,090	2,120	1,880	1,930	2,000	2,120	2,180	2,280	2,370		
			100	2,190	2,140	2,180	1,940	2,000	2,090	2,250	2,330	2,440	2,560		
			125	2,490	2,430	2,480	2,210	2,290	2,380	2,570	2,660	2,800	2,940		
	40	150	2,910	2,850	2,900	2,600	2,690	2,810	3,020	3,120	3,280	3,440			
		180	3,510	3,430	3,510	3,140	3,250	3,380	3,650	3,760	3,940	4,130			
		200	3,560	3,480	3,560	3,180	3,300	3,440	3,930	4,200	4,520	4,900			
		40	2,330	2,280	2,290	2,050	2,100	2,170	2,310	2,390	2,520	2,650			
		60	2,570	2,500	2,540	2,260	2,340	2,420	2,610	2,720	2,870	3,030			
		80	2,800	2,730	2,810	2,500	2,590	2,700	2,930	3,060	3,240	3,430			
	60	100	2,910	2,840	2,930	2,620	2,720	2,850	3,140	3,290	3,520	3,750			
		125	3,200	3,120	3,250	2,900	3,020	3,180	3,550	3,740	4,020	4,310			
		150	3,540	3,440	3,590	3,210	3,370	3,550	4,020	4,260	4,620	4,980			
		180	4,090	3,970	4,160	3,710	3,900	4,120	4,670	4,950	5,360	5,800			
		200	4,200	4,100	4,300	3,850	4,040	4,290	4,960	5,300	5,770	6,270			
		250	—	—	—	4,400	4,660	4,960	5,780	6,200	6,800	7,420			
	80	300	—	—	4,960	5,260	5,610	6,610	7,110	7,820	8,560				
		60	3,000	2,930	3,000	2,680	2,770	2,890	3,140	3,280	3,480	3,680			
		80	3,290	3,220	3,320	2,970	3,090	3,250	3,540	3,710	3,950	4,210			
		100	3,450	3,370	3,510	3,130	3,290	3,470	3,880	4,090	4,400	4,730			
		125	3,620	3,520	3,720	3,330	3,510	3,730	4,250	4,510	4,920	5,320			
		150	4,190	4,070	4,310	3,850	4,080	4,330	4,950	5,250	5,720	6,210			
	100	180	4,840	4,710	5,000	4,470	4,720	5,040	5,750	6,130	6,670	7,240			
		200	5,000	4,860	5,190	4,640	4,930	5,260	6,130	6,560	7,190	7,860			
		250	—	—	—	5,350	5,690	6,110	7,190	7,720	8,510	9,320			
		300	—	—	—	6,040	6,460	6,950	8,240	8,880	9,830	10,800			
		80	3,840	3,740	3,900	3,480	3,640	3,840	4,210	4,420	4,720	4,870			
		100	4,030	3,930	4,130	3,690	3,880	4,130	4,630	4,880	5,280	5,470			
125	125	4,250	4,120	4,390	3,930	4,170	4,450	5,110	5,420	5,920	6,180				
	150	4,910	4,770	5,100	4,570	4,840	5,180	5,940	6,330	6,900	7,210				
	180	5,680	5,510	5,900	5,290	5,620	6,020	6,930	7,370	8,060	8,430				
	200	5,880	5,700	6,140	5,510	5,870	6,320	7,380	7,910	8,710	9,120				
	250	—	—	—	6,350	6,790	7,340	8,670	9,330	10,320	10,840				
	300	—	—	—	7,190	7,720	8,360	9,970	10,760	11,930	12,570				
150	100	3,670	3,580	3,850	3,460	3,690	3,970	4,690	5,040	5,560	6,110				
	125	4,330	4,200	4,540	4,090	4,360	4,710	5,580	6,010	6,630	7,300				
	150	4,960	4,820	5,230	4,700	5,040	5,450	6,470	6,970	7,710	8,480				
	180	5,760	5,580	6,090	5,470	5,870	6,350	7,550	8,130	9,020	9,930				
	200	6,150	5,950	6,530	5,940	6,380	6,900	8,340	9,030	10,060	11,120				
	250	—	—	—	6,650	7,190	7,840	9,610	10,480	11,730	13,050				
180	300	—	—	—	7,830	8,480	9,260	11,380	12,410	13,910	15,480				
	125	—	—	—	4,750	5,100	5,520	6,570	7,080	7,830	8,630				
	150	—	—	—	5,530	5,940	6,440	7,670	8,260	9,160	10,100				
	180	—	—	—	6,430	6,910	7,510	8,960	9,650	10,720	11,820				
	200	—	—	—	6,970	7,520	8,180	9,890	10,710	11,950	13,230				
	250	—	—	—	7,830	8,500	9,310	11,430	12,460	13,990	15,560				
200	300	—	—	—	9,240	10,040	11,000	13,540	14,760	16,580	18,470				
	150	—	—	—	6,620	7,100	7,700	9,180	9,880	10,960	12,070				
	180	—	—	—	7,700	8,280	8,980	10,720	11,550	12,820	14,140				
	200	—	—	—	7,700	8,340	9,110	11,160	12,150	13,620	15,140				
	250	—	—	—	9,390	10,180	11,130	13,680	14,910	16,730	18,620				
	300	—	—	—	11,060	12,010	13,170	16,190	17,660	19,840	22,090				
250	180	—	—	—	9,220	9,920	10,760	12,840	13,830	15,340	16,920				
	200	—	—	—	10,010	10,780	11,720	14,160	15,360	17,110	18,940				
	250	—	—	—	11,230	12,190	13,340	16,370	17,840	20,020	22,270				
	300	—	—	—	13,250	14,390	15,760	19,380	21,140	23,740	26,440				
	200	—	—	—	9,040	9,870	10,890	13,670	15,010	16,980	19,020				
	250	—	—	—	10,930	11,960	13,210	16,680	18,340	20,780	23,320				
300	200	—	—	—	12,820	14,050	15,550	19,700	21,670	24,600	27,630				
	250	—	—	—	13,040	14,330	15,880	20,070	22,070	25,060	28,150				
	300	—	—	—	15,650	17,190	19,050	24,130	26,550	30,160	33,900				
300	—	—	—	18,720	20,570	22,790	28,870	31,770	36,070	40,540					



Order 注文例

型式 - A - B - T
SKD11WP - 100 - 100 - 25
T-SKD11WP - 250 - 250 - 20.01



Delivery 出荷日

3 日日出荷



Price 価格

■数量スライド価格 (1円未満切り捨て) P47

数量区分	標準対応	個別対応 大口
数量	1~4	5~9
値引率	基準単価	5% 10% 10% 20%

◎表示数量超えはWOSにてご確認ください。



Alterations 追加加工

型式 - A - B - T - (CC・AB・TK)
T-SKD11WP - 250 - 250 - 20.01 - TK1

Alterations	標準・板厚(T)0.01mm指定タイプに適用		
	C寸法変更	A・B寸法公差変更	T寸法公差変更
Code	CC	AB	TK
Spec.	全周の面取り寸法を変更します。 CC0 ±0.05 (C0.5) CC1 (C1)	A・B寸法の公差を変更します。 Code A・B公差 AB1 ±0.05 AB2 ±0.05 (規格公差) AB3 ±0.1 AB4 ±0.2 AB5 ±0.3	T寸法の公差を変更します。 Code T公差 TK1 ±0.05 TK2 ±0.05 (規格公差) TK3 ±0.2 TK4 ±0.01 TK5 ±0.02
¥/1Code	0	0	0

T-SKD11WP 板厚(T)0.01mm指定タイプ ¥基準単価

型式	A	B	T	¥基準単価					
				5.00~6.00	6.01~8.00	8.01~10.00	10.01~20.00	20.01~30.00	30.01~35.00
T-SKD11WP	20	20	20	2,360	2,280	2,030	2,120	2,170	2,210
			40	2,440	2,390	2,110	2,290	2,400	2,450
			60	2,510	2,470	2,190	2,420	2,570	2,650
			80	2,560	2,540	2,250	2,540	2,740	2,840
			100	2,620	2,620	2,330	2,700	2,930	3,070
			125	2,990	2,970	2,650	3,090	3,360	3,520
	40	150	3,490	3,490	3,120	3,630	3,940	4,130	
		180	4,210	4,210	3,770	4,380	4,730	4,950	
		200	4,270	4,280	3,810	4,720	5,430	5,870	
		40	2,800	2,750	2,460	2,770	3,030	3,180	
		60	3,080	3,050	2,720	3,130	3,450	3,630	
		80	3,360	3,370	3,000	3,520	3,890	4,120	
	60	100	3,490	3,510	3,140	3,770	4,220	4,500	
		125	3,840	3,890	3,480	4,260	4,830	5,170	
		150	4,240	4,310	3,850	4,820	5,540	5,970	
		180	4,900	4,990	4,450	5,610	6,430	6,960	
		200	5,050	5,160	4,620	5,950	6,920	7,530	
		250	—	—	5,290	6,940	8,160	8,910	
	80	300	—	—	5,950	7,930	9,380	10,270	
		60	3,590	3,600	3,210	3,770	4,180	4,420	
		80	3,950	3,990	3,560	4,250	4,750	5,050	
		100	4,140	4,210	3,760	4,650	5,280	5,680	
		125	4,350	4,460	4,000	5,100	5,900	6,390	
		150	5,030	5,170	4,620	5,940	6,860	7,450	
	100	180	5,810	6,000	5,370	6,910	8,000	8,690	
		200	5,990	6,220	5,570	7,360	8,630	9,430	
		250	—	—	6,420	8,630	10,210	11,190	
		300	—	—	7,240	9,890	11,790	12,960	
		80	4,610	4,680	4,170	5,060	5,660	5,840	
		100	4,840	4,960	4,430	5,550	6,330	6,570	
125	125	5,100	5,270	4,710	6,130	7,100	7,420		
	150	5,890	6,120	5,480	7,120	8,280	8,650		
	180	6,820	7,080	6,350	8,310	9,670	10,120		
	200	7,050	7,360	6,610	8,850	10,450	10,940		
	250	—	—	7,630	10,410	12,390	13,010		
	300	—	—	8,630	11,970	14,320	15,080		
150	100	4,410	4,610	4,150	5,620	6,680	7,330		
	125	5,190	5,450	4,900	6,700	7,960	8,760		
	150	5,960	6,280	5,640	7,760	9,250	10,180		
	180	6,920	7,310	6,570	9,060				