

S50C
6F6G
6面サーフェイス

GROUND PLATES


研磨プレート

—標準タイプ・フリーサイズタイプ—



■精度基準

- 基準面直角度 100mmに対し0.008以下
- 板厚平行度 100mmに対し0.008以下
- 平面度 (板厚T) T3.00~10.00 T10.01~20.00 T20.01~40.00 T40.01~50.00
100mmに対し 0.02 0.015 0.01 0.008

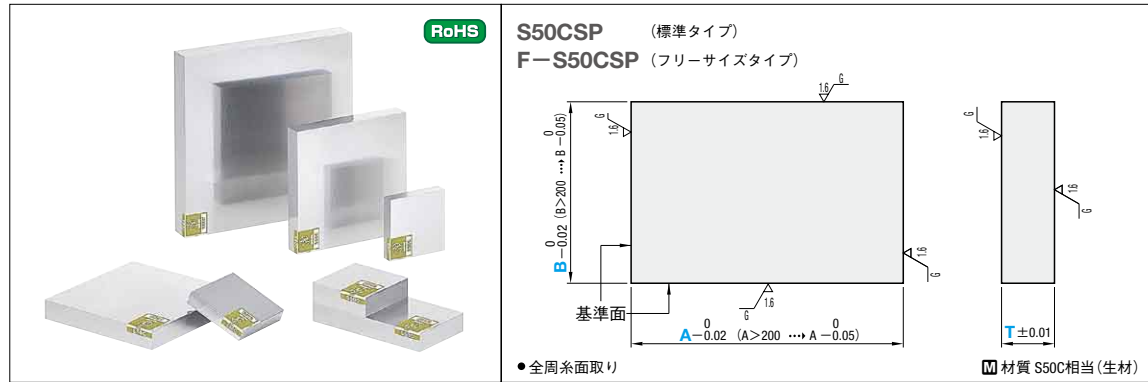

■S50CSP 標準タイプ ¥基準単価

型式	A	B	T	¥基準単価															
				3	5	6	8	10	13	15	20	25	30	35	40	50			
S50CSP	10	10	10	3,100	3,010	2,890	2,790	2,370	2,390	2,400	2,420	2,450	2,470	2,490	2,510	2,540			
			20	3,110	3,030	2,900	2,800	2,380	2,390	2,410	2,440	2,460	2,480	2,500	2,520	2,550			
			40	3,140	3,050	2,930	2,820	2,400	2,410	2,430	2,450	2,470	2,500	2,520	2,540	2,570			
			60	3,170	3,070	2,950	2,840	2,410	2,430	2,450	2,470	2,490	2,510	2,540	2,560	2,580			
			80	3,190	3,090	2,970	2,860	2,430	2,450	2,470	2,490	2,510	2,530	2,550	2,570	2,600			
			100	3,210	3,120	2,990	2,880	2,450	2,470	2,480	2,500	2,530	2,550	2,570	2,590	2,620			
	20	20	40	3,130	3,040	2,920	2,810	2,390	2,400	2,420	2,440	2,460	2,480	2,500	2,520	2,550			
			60	3,150	3,060	2,940	2,830	2,400	2,420	2,440	2,450	2,470	2,500	2,520	2,540	2,570			
			80	3,180	3,080	2,960	2,850	2,420	2,440	2,450	2,470	2,490	2,510	2,540	2,560	2,580			
			100	3,200	3,110	2,980	2,870	2,440	2,450	2,470	2,490	2,510	2,530	2,550	2,570	2,600			
			125	3,220	3,130	3,000	2,890	2,450	2,470	2,490	2,500	2,530	2,550	2,570	2,590	2,650			
			150	3,240	3,150	3,020	2,910	2,460	2,480	2,500	2,520	2,540	2,560	2,580	2,600	2,680			
	40	40	60	3,180	3,080	2,960	2,850	2,420	2,440	2,450	2,470	2,490	2,500	2,520	2,540	2,570			
			80	3,200	3,110	2,980	2,870	2,440	2,450	2,470	2,490	2,500	2,520	2,540	2,560	2,580			
			100	3,220	3,130	3,000	2,890	2,450	2,470	2,490	2,500	2,520	2,540	2,560	2,580	2,620			
			125	3,240	3,150	3,020	2,910	2,460	2,480	2,500	2,520	2,540	2,560	2,580	2,600	2,650			
			150	3,260	3,170	3,040	2,930	2,470	2,490	2,500	2,520	2,540	2,560	2,580	2,600	2,680			
			180	3,280	3,190	3,060	2,950	2,480	2,500	2,520	2,540	2,560	2,580	2,600	2,620	2,700			
	60	60	80	3,220	3,130	3,000	2,890	2,450	2,470	2,490	2,500	2,520	2,540	2,560	2,580	2,620			
			100	3,240	3,150	3,020	2,910	2,460	2,480	2,500	2,520	2,540	2,560	2,580	2,600	2,650			
			125	3,260	3,170	3,040	2,930	2,470	2,490	2,500	2,520	2,540	2,560	2,580	2,600	2,680			
			150	3,280	3,190	3,060	2,950	2,480	2,500	2,520	2,540	2,560	2,580	2,600	2,620	2,700			
			180	3,300	3,210	3,080	2,970	2,490	2,510	2,520	2,540	2,560	2,580	2,600	2,620	2,700			
			200	3,320	3,230	3,100	2,990	2,500	2,520	2,540	2,560	2,580	2,600	2,620	2,640	2,720			
	80	80	100	3,260	3,170	3,040	2,930	2,470	2,490	2,500	2,520	2,540	2,560	2,580	2,600	2,650			
			125	3,280	3,190	3,060	2,950	2,480	2,500	2,520	2,540	2,560	2,580	2,600	2,620	2,680			
			150	3,300	3,210	3,080	2,970	2,490	2,510	2,520	2,540	2,560	2,580	2,600	2,620	2,700			
			180	3,320	3,230	3,100	2,990	2,500	2,520	2,540	2,560	2,580	2,600	2,620	2,640	2,720			
			200	3,340	3,250	3,120	3,010	2,510	2,530	2,540	2,560	2,580	2,600	2,620	2,640	2,720			
			250	3,360	3,270	3,140	3,030	2,520	2,540	2,560	2,580	2,600	2,620	2,640	2,660	2,740			
100	100	125	3,300	3,210	3,080	2,970	2,490	2,510	2,520	2,540	2,560	2,580	2,600	2,620	2,680				
		150	3,320	3,230	3,100	2,990	2,500	2,520	2,540	2,560	2,580	2,600	2,620	2,640	2,700				
		180	3,340	3,250	3,120	3,010	2,510	2,530	2,540	2,560	2,580	2,600	2,620	2,640	2,720				
		200	3,360	3,270	3,140	3,030	2,520	2,540	2,560	2,580	2,600	2,620	2,640	2,660	2,740				
		250	3,380	3,290	3,160	3,050	2,530	2,550	2,560	2,580	2,600	2,620	2,640	2,660	2,740				
		300	3,400	3,310	3,180	3,070	2,540	2,560	2,580	2,600	2,620	2,640	2,660	2,680	2,760				
125	125	150	3,340	3,250	3,120	3,010	2,510	2,530	2,540	2,560	2,580	2,600	2,620	2,640	2,700				
		180	3,360	3,270	3,140	3,030	2,520	2,540	2,560	2,580	2,600	2,620	2,640	2,660	2,720				
		200	3,380	3,290	3,160	3,050	2,530	2,550	2,560	2,580	2,600	2,620	2,640	2,660	2,740				
		250	3,400	3,310	3,180	3,070	2,540	2,560	2,580	2,600	2,620	2,640	2,660	2,680	2,760				
		300	3,420	3,330	3,200	3,090	2,550	2,570	2,580	2,600	2,620	2,640	2,660	2,680	2,760				
		350	3,440	3,350	3,220	3,110	2,560	2,580	2,600	2,620	2,640	2,660	2,680	2,700	2,780				
150	150	180	3,380	3,290	3,160	3,050	2,530	2,550	2,560	2,580	2,600	2,620	2,640	2,660	2,720				
		200	3,400	3,310	3,180	3,070	2,540	2,560	2,580	2,600	2,620	2,640	2,660	2,680	2,740				
		250	3,420	3,330	3,200	3,090	2,550	2,570	2,580	2,600	2,620	2,640	2,660	2,680	2,760				
		300	3,440	3,350	3,220	3,110	2,560	2,580	2,600	2,620	2,640	2,660	2,680	2,700	2,780				
		350	3,460	3,370	3,240	3,130	2,570	2,590	2,600	2,620	2,640	2,660	2,680	2,700	2,780				
		400	3,480	3,390	3,260	3,150	2,580	2,600	2,620	2,640	2,660	2,680	2,700	2,720	2,800				
180	180	200	3,420	3,330	3,200	3,090	2,550	2,570	2,580	2,600	2,620	2,640	2,660	2,680	2,740				
		250	3,440	3,350	3,220	3,110	2,560	2,580	2,600	2,620	2,640	2,660	2,680	2,700	2,760				
		300	3,460	3,370	3,240	3,130	2,570	2,590	2,600	2,620	2,640	2,660	2,680	2,700	2,780				
		350	3,480	3,390	3,260	3,150	2,580	2,600	2,620	2,640	2,660	2,680	2,700	2,720	2,800				
		400	3,500	3,410	3,280	3,170	2,590	2,610	2,620	2,640	2,660	2,680	2,700	2,720	2,800				
		450	3,520	3,430	3,300	3,190	2,600	2,620	2,640	2,660	2,680	2,700	2,720	2,740	2,820				
200	200	250	3,460	3,370	3,240	3,130	2,570	2,590	2,600	2,620	2,640	2,660	2,680	2,700	2,760				
		300	3,480	3,390	3,260	3,150	2,580	2,600	2,620	2,640	2,660	2,680	2,700	2,720	2,800				
		350	3,500	3,410	3,280	3,170	2,590	2,610	2,620	2,640	2,660	2,680	2,700	2,720	2,800				
		400	3,520	3,430	3,300	3,190	2,600	2,620	2,640	2,660	2,680	2,700	2,720	2,740	2,820				
		450	3,540	3,450	3,320	3,210	2,610	2,630	2,640	2,660	2,680	2,700	2,720	2,740	2,820				
		500	3,560	3,470	3,340	3,230	2,620	2,640	2,660	2,680	2,700	2,720	2,740	2,760	2,840				
250	250	300	3,500	3,410	3,280	3,170	2,590	2,610	2,620	2,640	2,660	2,680	2,700	2,720	2,780				
		350	3,520	3,430	3,300	3,190	2,600	2,620	2,640	2,660	2,680	2,700	2,720	2,740	2,820				
		400	3,540	3,450	3,320	3,210	2,610	2,630	2,640	2,660	2,680	2,700	2,720	2,740	2,820				
		450	3,560	3,470	3,340	3,230	2,620	2,640	2,660	2,680	2,700	2,720	2,740	2,760	2,840				
		500	3,580	3,490	3,360	3,250	2,630	2,650	2,660	2,680	2,700	2,720	2,740	2,760	2,840				
		550	3,600	3,510	3,380	3,270	2,640	2,660	2,680	2,700	2,720	2,740	2,760	2,780	2,860				
300	300	350	3,540	3,450	3,320	3,210	2,610	2,630	2,640	2,660	2,680	2,700	2,720	2,740	2,820				
		400	3,560	3,470	3,340	3,230	2,620	2,640	2,660	2,680	2,700	2,720	2,740	2,760	2,840				
		450	3,580	3,490	3,360	3,250	2,630	2,650	2,660	2,680	2,700	2,720	2,740	2,760	2,840				
		500	3,600	3,510	3,380	3,270	2,640	2,660	2,680	2,700	2,720	2,740	2,760	2,780	2,860				
		550	3,620	3,530	3,400	3,290	2,650	2,670	2,680	2,700	2,720	2,740	2,760	2,780	2,860				
		600	3,640	3,550	3,420	3,310	2,660	2,680	2,700	2,720	2,740	2,760	2,780	2,800	2,880				

Order 注文例
型式 - A - B - T
S50CSP - 100 - 100 - 25
F-S50CSP - 250.02 - 249.98 - 20.01

Delivery 出荷日
3 日日出荷

Price 価格
■数量スライド価格 (1円未満切り捨て) P47
数量区分 標準対応 個別対応 大口
数量 1~4 5~9 10~19 20~
値引率 基準単価 5% 10% お見積り
○表示数量超えはWOSにてご確認ください。

Alterations 追加工
型式 - A - B - T - (CC・AB・TK)
F-S50CSP - 250.02 - 249.98 - 20.01 - CC0

Alterations	標準・フリーサイズに適用		
	C寸法変更	A・B寸法公差変更	T寸法公差変更