


NEW

QUICK CHANGER SINGLE MODULE / SIGNAL LINE CONNECTOR

QUICK CHANGER SIGNAL MODULE / SIGNAL LINE CONNECTOR

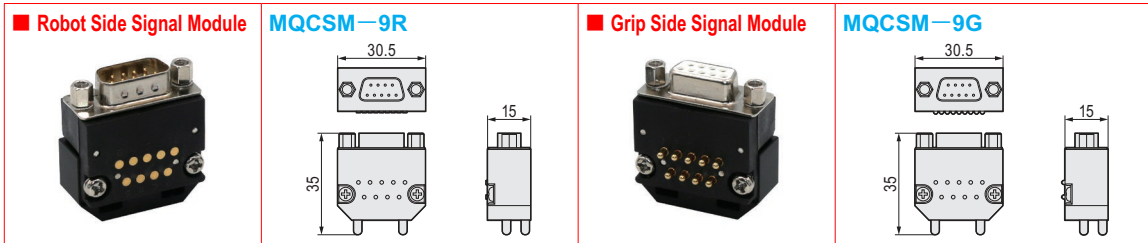

Part Number	No.	I/O wiring method	Operating current (A)	Decomposition voltage	Operating temp. range	Contact surface treatment	Applicable quick changer type
MQCSM	9R	9-pin D-SUB	5	500V AC (1 min)	-55°C ~ +125°C	Surface gold plating	MQC-R-90
	9G						MQC-R-150
							MQC-R-200
							MQC-G-90
							MQC-G-150
							MQC-G-200



Order

Part Number — No.
MQCSM — **9R**



Example





Days to Ship

Quotation



Price

Quotation

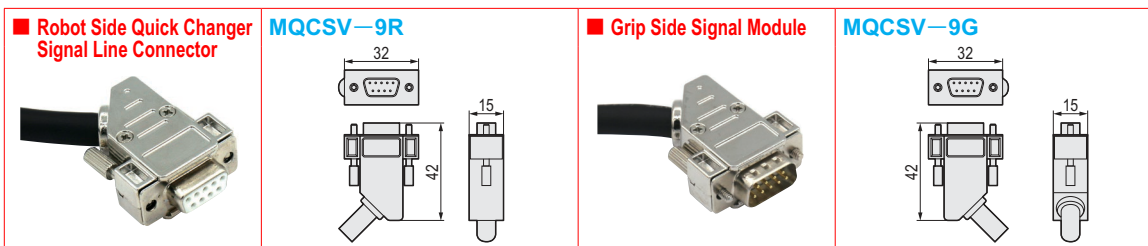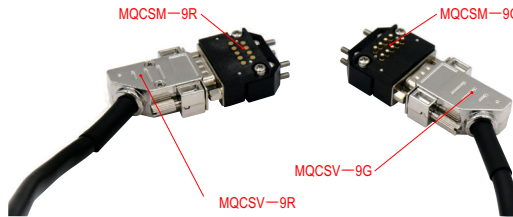

Part Number	No.	I/O wiring method	Operating current (A)	Decomposition voltage	Operating temp. range	Contact surface treatment	Applicable quick changer signal module
MQCSV	9R	9-pin D-SUB	5	500V AC (1 min)	-55°C ~ +125°C	Surface gold plating	MQCSM-9R
	9G						MQCSM-9G



Order

Part Number — No.
MQCSV — **9R**



Example



Days to Ship

Quotation



Price

Quotation

