

SIMPLE FLOW METER

-TAPERED-

■ **Application** Use to perform simple flow rate check.



■ **Features**

- M-FLM-T-33R-TM is equipped with a simple thermometer.
- The resin part is hexagonal; to hook onto the tool.

☑ **Material:** Polyamide/Brass







Usable temperature (Oil) (°C)	120 or less
Usable temperature (Water) (°C)	80 or less
Allowable pressure (MPa)	0.98
Max. flow rate (l/min)	10

M-FLM-T-33

M-FLM-T-22

M-FLM-T-3R3

M-FLM-T-33R-TM

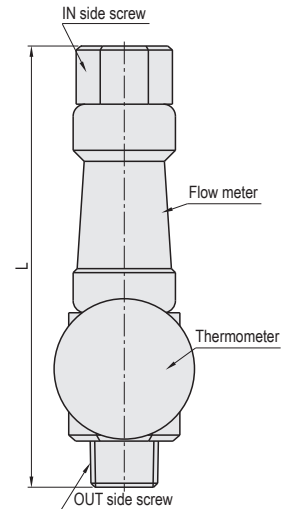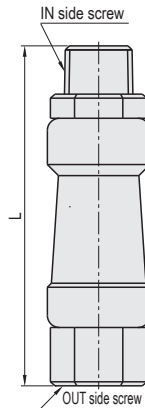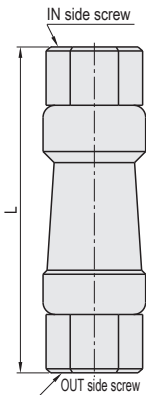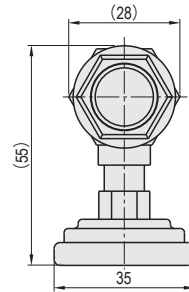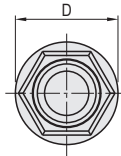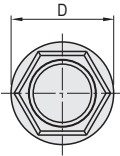

L	D	IN side screw	OUT side screw	Part Number		Unit Price 1-3 pcs
				Type	No.	
81	25.5	RC(PT)1/4	RC(PT)1/4	M-FLM-T	22	Quotation
		RC(PT)3/8	RC(PT)3/8		33	
85	-	R(PT)3/8	RC(PT)3/8		3R3	
		RC(PT)3/8	R(PT)3/8		33R-TM	



Order

Part Number

M-FLM-T-33



Days to Ship

Quotation



Price

Quotation