


ミスミ

T SLOT CUTTERS

## Tスロットカッター

●千鳥刃・ロングシャンクタイプ -STAGGERED FLUTE / LONG SHANK-

LTSC

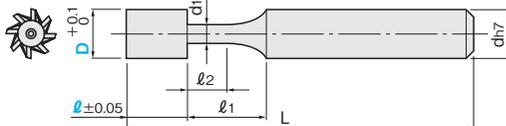

⚠外周、両サイド共に切れ刃があります。

材質



仕様



型番 **LTSC** 1本単位

刃径 D	刃幅ℓ(選択)																									首径 d1	首長 ℓ1	首長 ℓ2	全長 L	シャンク径 d	刃数 Z
	3	4	5	6	7	8	9	10	11	12	13	14	15	16	17	18	19	20	21	22	23	24	25								
15	●	●	●	●	●	●	●	●																		8	10	6	120	12	8
16	●	●	●	●	●	●	●	●																		8	10	6	120	12	8
18	●	●	●	●	●	●	●	●	●																	9	10	6	150	12	10
20	●	●	●	●	●	●	●	●	●	●																10	10	8	150	12	10
22	●	●	●	●	●	●	●	●	●	●																11	10	8	150	12	10
25	●	●	●	●	●	●	●	●	●	●	●															14	12	9	150	16	10
28	●	●	●	●	●	●	●	●	●	●	●	●														14	12	9	150	16	12
30	●	●	●	●	●	●	●	●	●	●	●	●	●													15	12	11	150	16	12
32	●	●	●	●	●	●	●	●	●	●	●	●	●	●												15	12	11	150	16	12
35	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●											15	12	11	150	16	12
38	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●										19	20	19	150	20	12
40	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●									19	20	19	180	20	12
45	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●								19	20	19	180	20	14
50	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●							19	20	19	180	20	14
60	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●						24	20	19	200	25	14



Price  
価格

■数量スライド価格 (◎1円未満切捨て)

数量	1~4	5~9	10~19	20~29	30~	お見積り
値引率	価格表	3%	5%	7%		

刃径 D	¥通常単価 1~4本		
	刃幅ℓ 3~10	刃幅ℓ 11~20	刃幅ℓ 21~25
15	4,400	—	—
16	5,240	—	—
18	5,780	6,380	—
20	5,820	6,410	—
22	6,310	6,950	—
25	6,640	7,320	—
28	7,970	8,790	—
30	9,460	10,410	—
32	10,960	12,060	—
35	12,300	13,530	—
38	14,340	15,780	—
40	15,780	17,360	—
45	19,110	21,020	23,100
50	22,420	24,660	27,130
60	28,930	31,990	35,160

切削条件 P.684



Order  
注文例

**LTSC 20 - 10**

型番 刃径 (D) 刃幅 (ℓ)



Delivery  
出荷日

**3** 日目出荷



ストック A 800円/1本

巻末-5

◎同一サイズ3本以上は一律2,160円

ランナー溝

スプルーランナー  
ロック穴

ピンポイント  
ゲート

サブマリン  
ゲート

食い切り溝

座繰り

成形用プランク

Tスロット

リング溝

サイドカッター

沈めフライス